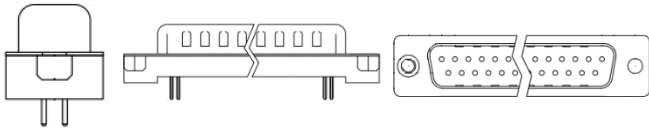
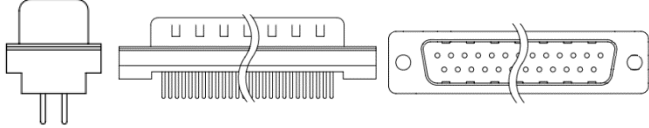
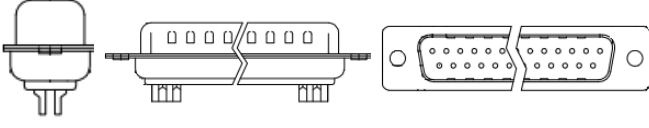
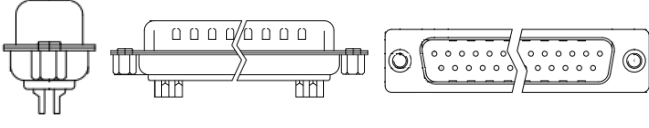
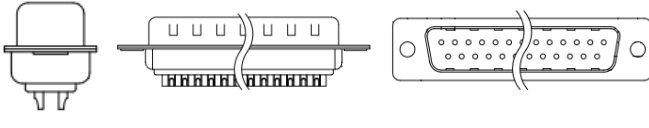
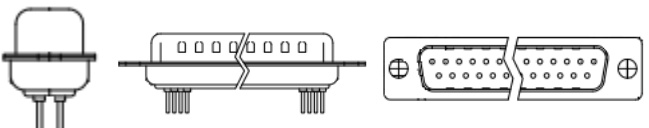
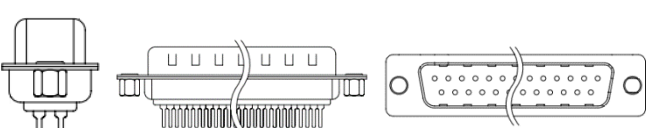
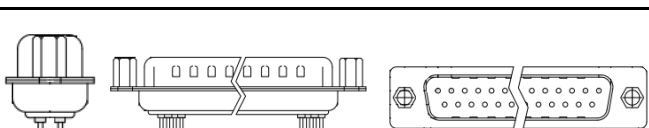
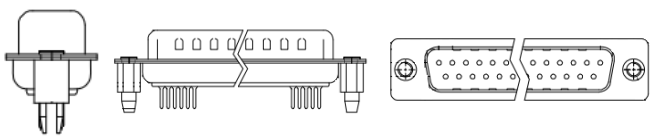
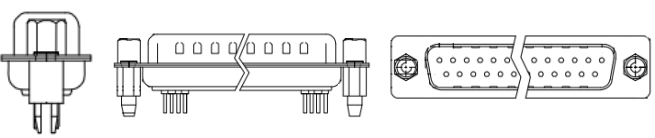
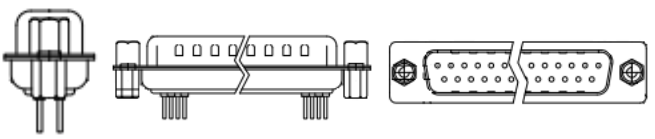
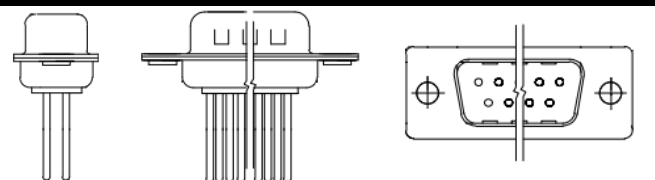
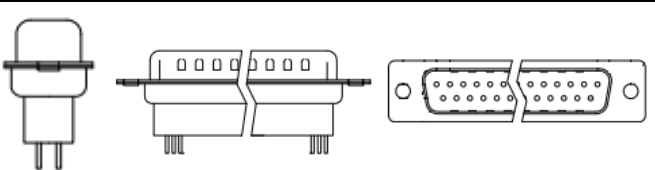
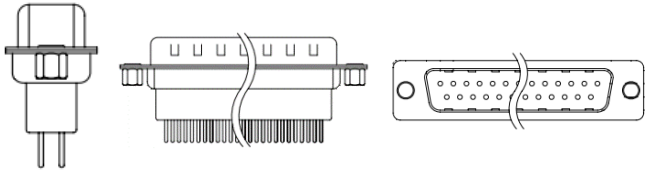
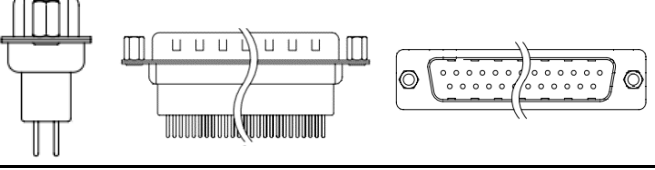
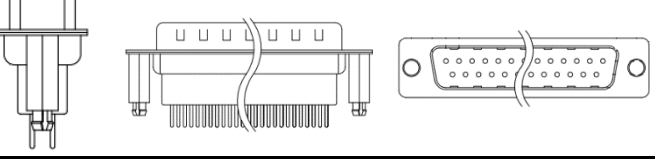








D-Subminiature Plugs

Quick Reference Guide #3			
D-Sub Flush Mount Straight PCB Plug (DXXX-PA-M1 and DXXX-PA-M2)			
DE09-PA-M1 DA15-PA-M1 DB25-PA-M1 DC37-PA-M1	Multiple contacts (9, 15, 25, 37), through hole mounting		
DE09-PA-M2 DA15-PA-M2 DB25-PA-M2 DC37-PA-M2	Multiple contacts (9, 15, 25, 37), #4-40 threaded mounting holes		
D-Sub Solder Cup Plug (DXXX-PD, DXXX-PD-SL, and DXXX-PD-MC)			
DE09-PD DA15-PD DB25-PD DC37-PD	Multiple contacts (9, 15, 25, 37), .120" [3.05mm] mounting holes		
DE09-PD-SL DA15-PD-SL DB25-PD-SL DC37-PD-SL	Multiple contacts (9, 15, 25, 37), bottom side riveted #4-40 clinch nuts		
DE09-PD-MC DA15-PD-MC DB25-PD-MC DC37-PD-MC	Multiple contacts (9, 15, 25, 37), .118" [3.00mm] mounting holes, machined pin		
D-Sub Standard Profile Straight PCB Plug – Standard Tail Length (DXXX-PT-1, DXXX-PT-1-SL, DXXX-PT-1-JS, DXXX-PT-1-BL, DXXX-PT-1-BL-JS, and DXXX-PT-1-SL-JS)			
DE09-PT-1 DA15-PT-1 DB25-PT-1 DC37-PT-1	Multiple contacts (9, 15, 25, 37), .120" [3.05mm] mounting holes		
DE09-PT-1-SL DA15-PT-1-SL DB25-PT-1-SL DC37-PT-1-SL	Multiple contacts (9, 15, 25, 37), bottom side riveted #4-40 clinch nuts		
DE09-PT-1-JS DA15-PT-1-JS DB25-PT-1-JS DC37-PT-1-JS	Multiple contacts (9, 15, 25, 37), top side riveted #4-40 jackscrews		

D-Subminiature Plugs

DE09-PT-1-BL DA15-PT-1-BL DB25-PT-1-BL DC37-PT-1-BL	Multiple contacts (9, 15, 25, 37), riveted #4-40 standoffs, board locks	
DE09-PT-1-BL-JS DA15-PT-1-BL-JS DB25-PT-1-BL-JS DC37-PT-1-BL-JS	Multiple contacts (9, 15, 25, 37), riveted #4-40 jackscrews and standoffs, board locks	
DE09-PT-1-SL-JS DA15-PT-1-SL-JS DB25-PT-1-SL-JS DC37-PT-1-SL-JS	Multiple contacts (9, 15, 25, 37), riveted #4-40 clinch nuts and jackscrews	
D-Sub Standard Profile Straight PCB Plug – Wire Wrap Tail (DXXX-PT-2)		
DE09-PT-2 DA15-PT-2 DB25-PT-2 DC37-PT-2	Multiple contacts (9, 15, 25, 37), .120" [3.05mm] mounting holes	
D-Sub High Profile Straight PCB Plug – Standard Tail Length (DXXX-PE-1, DXXX-PE-1-SL, DXXX-PE-1-JS, DXXX-PE-1-BL, and DXXX-PE-1-BL-JS)		
DE09-PE-1 DA15-PE-1 DB25-PE-1 DC37-PE-1	Multiple contacts (9, 15, 25, 37), .120" [3.05mm] mounting holes	
DE09-PE-1-SL DA15-PE-1-SL DB25-PE-1-SL DC37-PE-1-SL	Multiple contacts (9, 15, 25, 37), bottom side riveted #4-40 clinch nuts	
DE09-PE-1-JS DA15-PE-1-JS DB25-PE-1-JS DC37-PE-1-JS	Multiple contacts (9, 15, 25, 37), top side riveted #4-40 jackscrews	
DE09-PE-1-BL DA15-PE-1-BL DB25-PE-1-BL DC37-PE-1-BL	Multiple contacts (9, 15, 25, 37), riveted #4-40 standoffs, board locks	

D-Subminiature Plugs

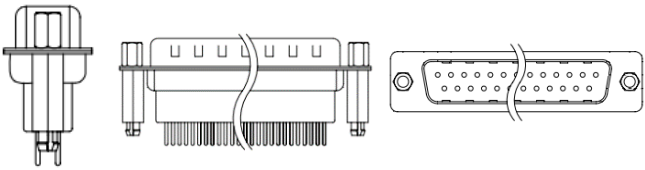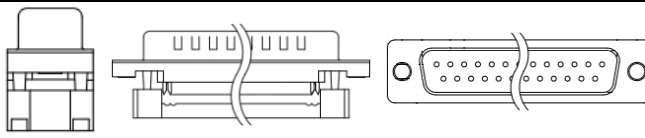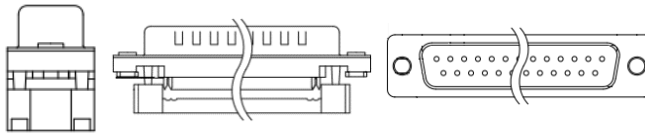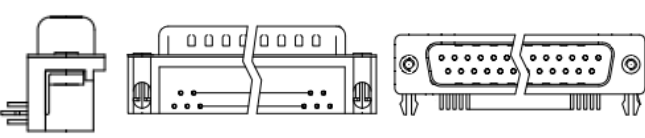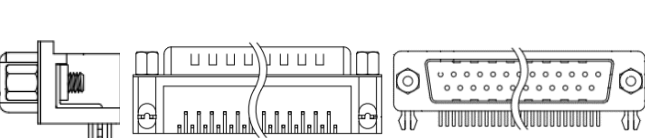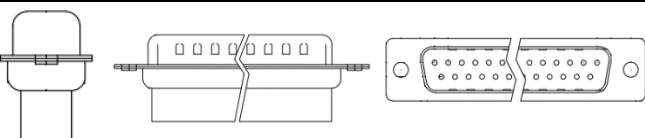DE09-PE-1-BL-JS DA15-PE-1-BL-JS DB25-PE-1-BL-JS DC37-PE-1-BL-JS	Multiple contacts (9, 15, 25, 37), riveted #4-40 jackscrews and standoffs, board locks	
D-Sub Flat Cable IDC Plug (DXXX-PF-M1 and DXXX-PF-M2)		
DE09-PF-M1 DA15-PF-M1 DB25-PF-M1 DC37-PF-M1	Multiple contacts (9, 15, 25, 37), metal shell, .130" [3.30mm] mounting holes	
DE09-PF-M2 DA15-PF-M2 DB25-PF-M2 DC37-PF-M2	Multiple contacts (9, 15, 25, 37), metal shell, #4-40 threaded mounting holes	
D-Sub Right Angle Plug – .318" [8.08mm] Footprint (DXXX-PL-24 and DXXX-PL-25)		
DE09-PL-24 DA15-PL-24 DB25-PL-24 DC37-PL-24	Multiple contacts (9, 15, 25, 37), forked board locks, #4-40 flush threaded inserts	
DE09-PL-25 DA15-PL-25 DB25-PL-25 DC37-PL-25	Multiple contacts (9, 15, 25, 37), forked board locks, #4-40 flush threaded inserts with removable jackscrews	
D-Sub Crimp and Poke Plug (DXXX-PR and DXXX-PR-SL)		
DE09-PR DA15-PR DB25-PR DC37-PR	Multiple contacts (9, 15, 25, 37), .120" [3.05mm] mounting holes	
DE09-PR-SL DA15-PR-SL DB25-PR-SL DC37-PR-SL	Multiple contacts (9, 15, 25, 37), bottom side riveted #4-40 clinch nuts	