


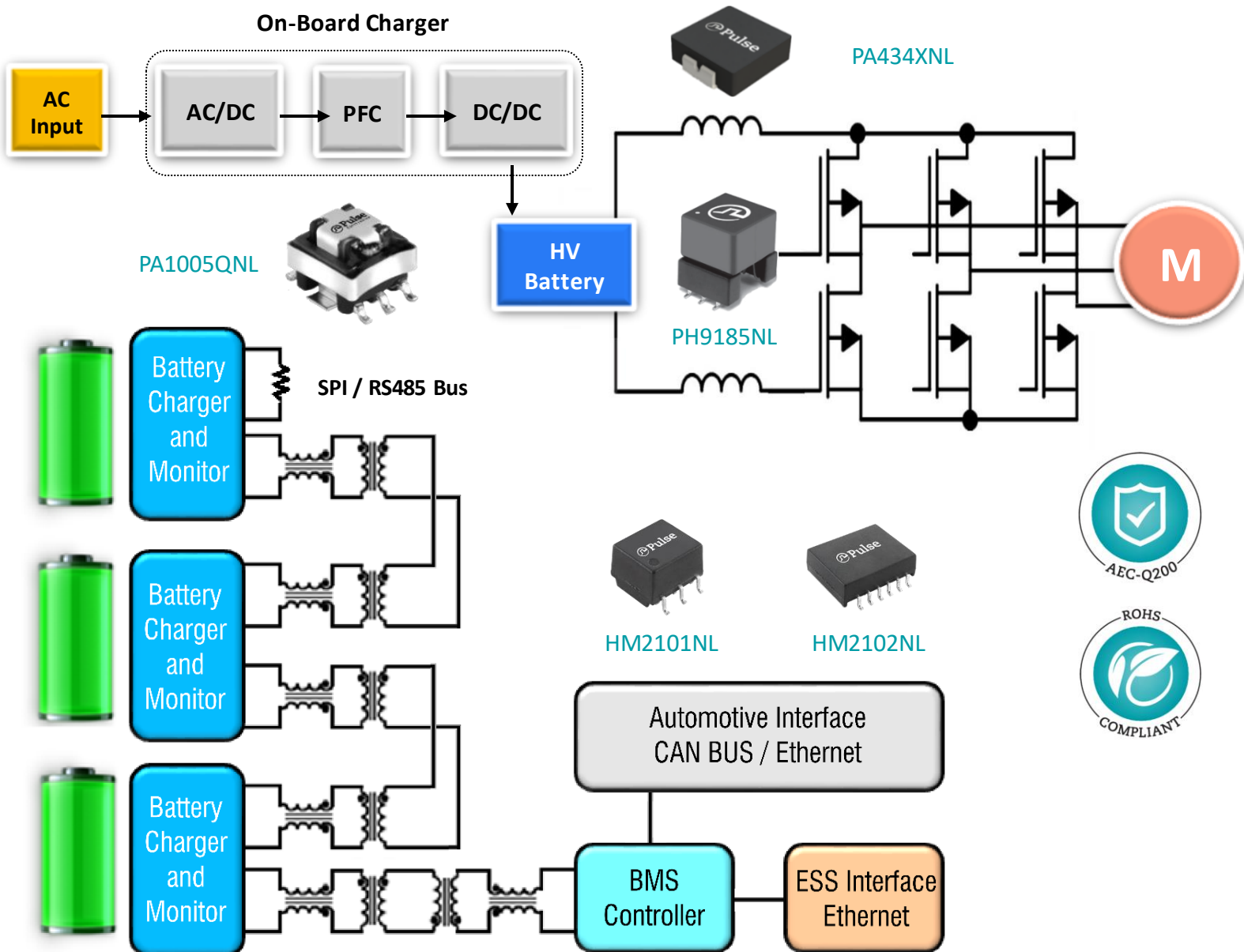
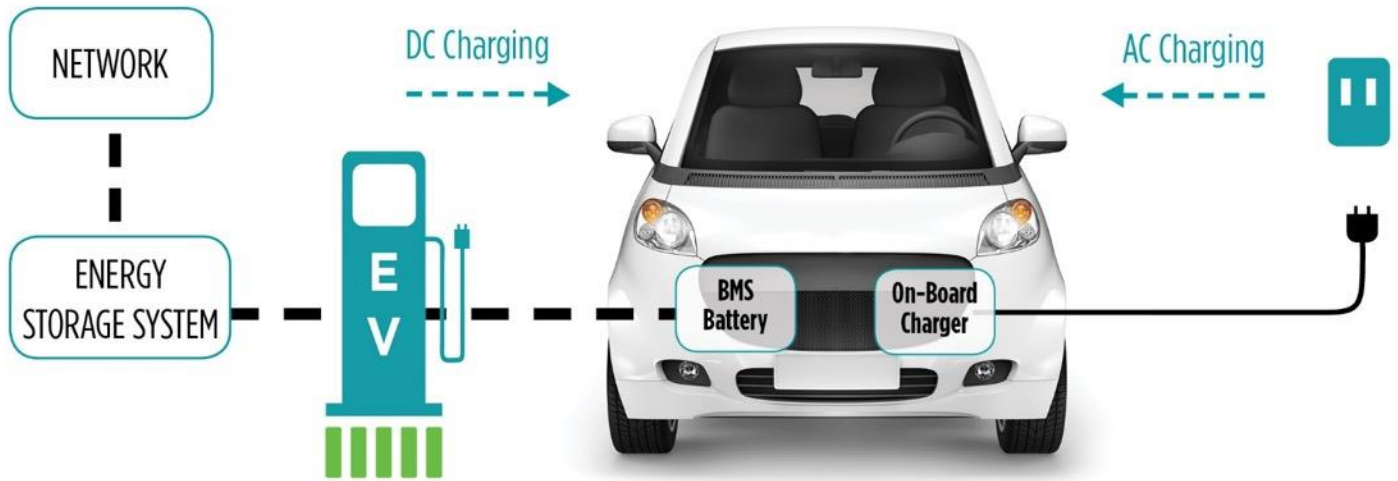


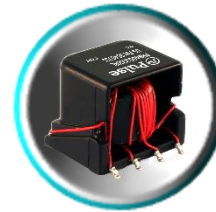

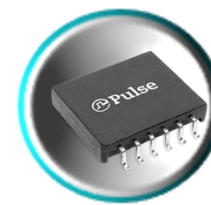

| PA434x                          | PH9185                   | PH9385                   | PA1005.XXXQNL                 | PH9400NL                      |
|---------------------------------|--------------------------|--------------------------|-------------------------------|-------------------------------|
| High Current Inductors          | High Isolation 5000 Vrms | High Isolation 4000 Vrms | High Frequency CT             | High Isolation 5000Vrms       |
| High Performance EMI Choke      | Reinforced Insulation    | Basic Insulation         | RMS Current – up to 20A       | Basic & Reinforced Insulation |
| Excellent temperature stability | 8mm Creepage             | 12mm Creepage            | Low Direct Current Resistance | 12mm Creepage                 |
| Corrosion Resistant Surface     | Up to 3 Watts            | Up to 2.5 Watts          | Hi-pot Voltage –up to 900Vrms | Up to 8W of Driver Power      |
| -40~125°C and -55~155°C         | -40~125°C                | -40~125°C                | -40~125°C                     | -40~125°C                     |

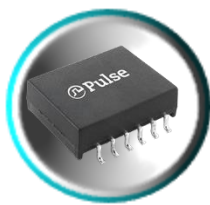

| HM2101NL                                       | HM2102NL                                      | HM2103NL                                      | HM2112ZNL                                     | HM2113ZNL                                     |
|------------------------------------------------|-----------------------------------------------|-----------------------------------------------|-----------------------------------------------|-----------------------------------------------|
| 1 Channel                                      | 2 Channel                                     | 1 Channels                                    | 2 Channels                                    | 1 Channels                                    |
| 1000VDC Working Voltage, Functional Insulation | 1600VDC Working Voltage Functional Insulation | 1000VDC Working Voltage Functional Insulation | 1000VDC Working Voltage Functional Insulation | 1000VDC Working Voltage Functional Insulation |
| 4300VDC Hi-Pot                                 | 4300VDC Hi-Pot                                | 4300VDC Hi-Pot                                | 4300VDC Hi-Pot                                | 4300VDC Hi-Pot                                |
| No Center Tap                                  | Center Tap                                    | Center Tap                                    | Center Tap                                    | Center Tap                                    |
| Common Choke                                   | Common Choke                                  | Common Choke                                  | Common Choke                                  | Common Choke                                  |
| -40~125°C                                      | -40~125°C                                     | -40~125°C                                     | -40~125°C                                     | -40~125°C                                     |