

MAN & MACHINE

ESTABLISHED 1982

D COOL

*Sealed Backlight Budget
Friendly Keyboard*


CHOICE IS EVERYTHING

Backlight



Standard backlight featuring
two levels of illumination

Lockable

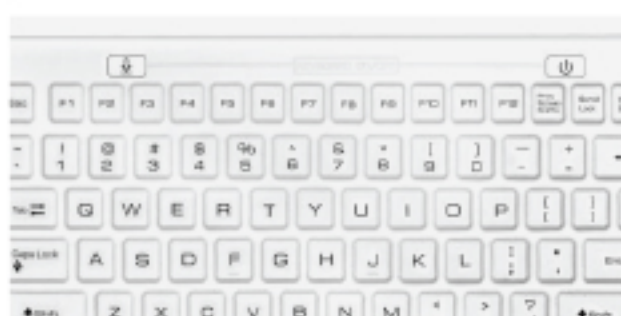

No need to disconnect
during cleaning

Low Profile



Sealed low profile
key design

Washable IP67



Wash. Spray. Wipe.

SPECIFICATIONS

- IP67
- Color: White or Black
- Size: 15x5.1x4(in)
- Weight: 1.28 lbs
- Cable Length: 70.8 (in)
- Operating Temp: 32 °F to 158 °F
- Storage Temp: 4 °F to 158 °F
- Power Consumption: 5V, 26mA
- Platform: Windows, MAC & Linux
- Connection: USB
- Number of keys: 110
- Switch Rating: 2 million
- 1-year Warranty

PAIR WITH A MIGHTY MOUSE PETITE MOUSE FOR A COMPLETE SEALED SOLUTION

