

RJ45 JACKS

PRODUCT GUIDE



TABLE OF CONTENTS

2.5G


CTRJPPS2R5GF..... 3

5G

CTRJPPS5GF..... 3

10G

CTRJPPS10GF..... 3

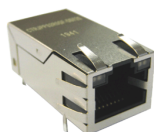

CTRJPPS2R5GF

2.5G

Description

2.5G Base-T integrated RJ45 jack, single port, PoE & PoE+, Tab up

Application Use

Telecom equipment, HUB, wireless router station, VoIP device, video camera

Operating Temp	Hi-Pot	Size (mm)
0°C to 70°C	2250 Vdc at 60Hz	32.6L x 16.6W x 13.5H



CTRJPPS5GF

5G

Description

5G Base-T integrated RJ45 jack, single port, PoE & PoE+, Tab up

Application Use

Telecom equipment, HUB, wireless router station, VoIP device, video camera

Operating Temp	Hi-Pot	Size (mm)
0°C to 70°C	1500 Vrms at 60Hz	32.6L x 16.6W x 13.5H



CTRJPPS10GF

10G

Description

10G Base-T integrated RJ45 jack, single port, PoE & PoE+, Tab up

Application Use

Telecom equipment, HUB, wireless router station, VoIP device, video camera

Operating Temp	Hi-Pot	Size (mm)
0°C to 70°C	1500 Vrms at 60Hz	32.6L x 16.6W x 13.5H

